

## SUMMARY

### # Wires



*Image is for illustrative purpose only*

Series	0B
Termination type	No contacts / Accessory
IP rating	0
AWG wire size	0.00 - 0.00
Cable Ø	4.50 - 5.20 mm
Status	Active

### Download

[Request a quote](#)

[Catalog](#)

## TECHNICAL DETAILS

### Mechanics

Shell Style/Model	GMA*: Bend relief Yellow
Keying	No keying
Housing Material	Thermoplastic polyurethane elastomer (Elastollan 1185 A)
Variant	J : Yellow
Weight	.42 g

### Performance

Configuration

Insulator


Rated Current

### Others

Temp (min / max): -40°C / +80°C

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## DRAWINGS

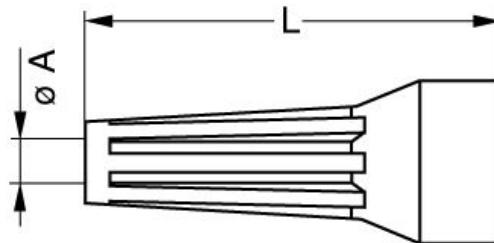

No keying

### Dimensions

	A	L
mm.	4.5	24
in.	0,18	0,94

## RECOMMENDED BY LEMO

### Tools

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.