



DATE: _____ LOCATION: _____

TYPE: _____ PROJECT: _____

CATALOG #: _____

Preset Slide Dimmer

FEATURES

- Designed specifically for use with 0–10V LED drivers and fluorescent ballasts
- No power pack required for controlling 0–10V drivers or ballasts
- Linear slide bar for superior quality and dimming performance
- Separate ON/OFF switch and dim bar to preserve preset light level
- Can be used in single-pole or 3-way applications
- Compatible with decorator-style wall plates
- Fits easily into a standard wallbox and is suitable for multi-gang installations



SPECIFICATIONS

ELECTRICAL

- Standard ON/OFF
- Frequency: 60Hz
- Voltage: 120/277VAC
- Load Rating: 10A, 1200VA, 1500VA
- Load Type: 0–10V, 0–10V Fluorescent (120V), 0–10V Fluorescent (277V)
- Switch Type: Single-Pole & 3-Way
- Protection: Radio/TV Filter protection
- Forward Phase 0–10V Control

MOUNTING

- Single-gang NEMA-style switch box (standard wall switch box)
- Decorator-style wall plate not included

OPERATING ENVIRONMENT

- Operating Temperature: 0°C to 55°C
- Storage Temperature: -10°C to 85°C
- Relative Humidity: 20% to 90% Non-Condensing

COLOR

- White with Ivory and Light Almond color change kits included. Additional color change kits sold separately

CERTIFICATIONS

- cCSAus, ISO9001

WARRANTY

- 5 year warranty
- See [HLI Standard Warranty](#) for additional information

ORDERING GUIDE

Example: PSD710–UNV–WVL


CATALOG #

Model	Color
PSD710-UNV Preset Slide Dimmer for 0–10V LED Drivers and Fluorescent Ballasts, Single Pole or 3-Way, 1200–1500VA 120/277VAC	WVL White with Ivory & Light Almond Color Change Kits
COLOR KIT Model	Color
PSDKIT-LL Preset Slide Dimmer Color Change Kit for PSD710 Dimmer	WH White
	IV Ivory
	LA Light Almond
	GY Gray
	BK Black
	BN Brown
	RD Red




Preset Slide Dimmer

DIMENSIONS

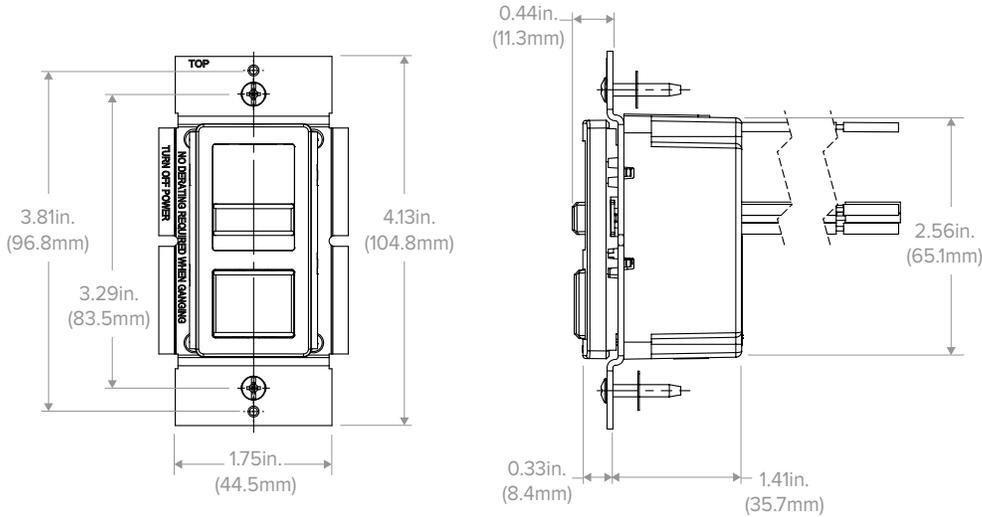

WIRING DIAGRAM

SINGLE LOCATION CONTROL

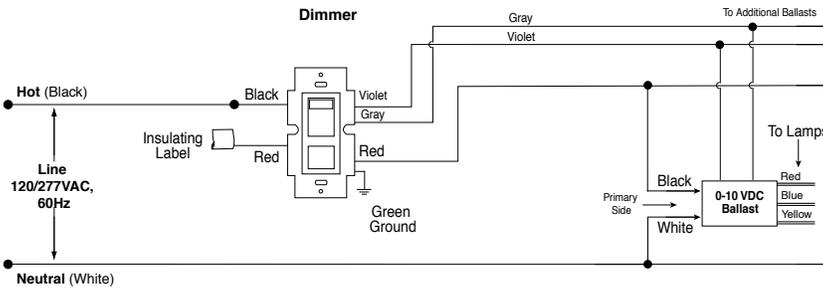

TWO LOCATION CONTROL

